 




Order Code	TCK-194
Inductance (each winding)	180 μ H \pm 35% (at 100 kHz / 100 mV)
Impedance (DCR)	5 m Ω max.
Rated Current	16 A max.
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions



Impedance Curve

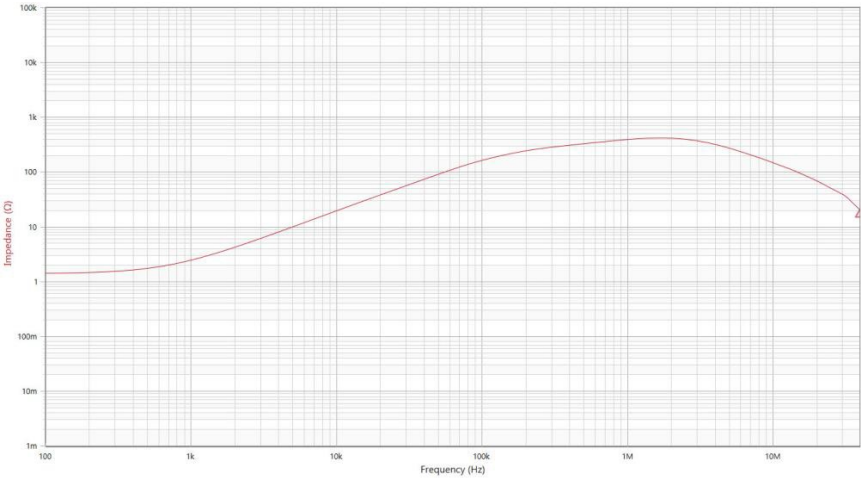

Outline Dimensions

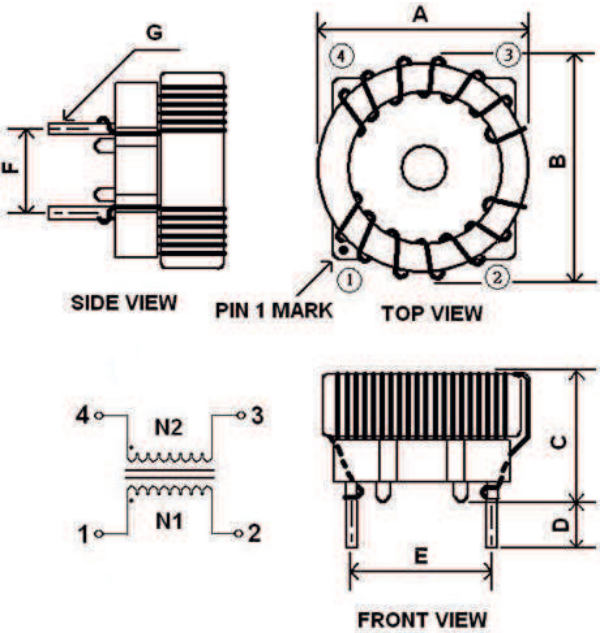

Dimensions [mm]	
A	16.0 max.
B	18.0 max.
C	16.5 max.
D	3.6 \pm 0.4
E	10.0 \pm 0.3
F	7.4 \pm 0.3
G	\varnothing 0.8 \pm 0.1

All specifications valid at +25°C, unless otherwise stated.