






Order Code	TCK-078
Inductance	1.1 $\mu\text{H} \pm 20\%$ (at 100 kHz / 250 mV)
Impedance (DCR)	15 m Ω max.
Rated Current	3.24 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-078



Impedance Curve

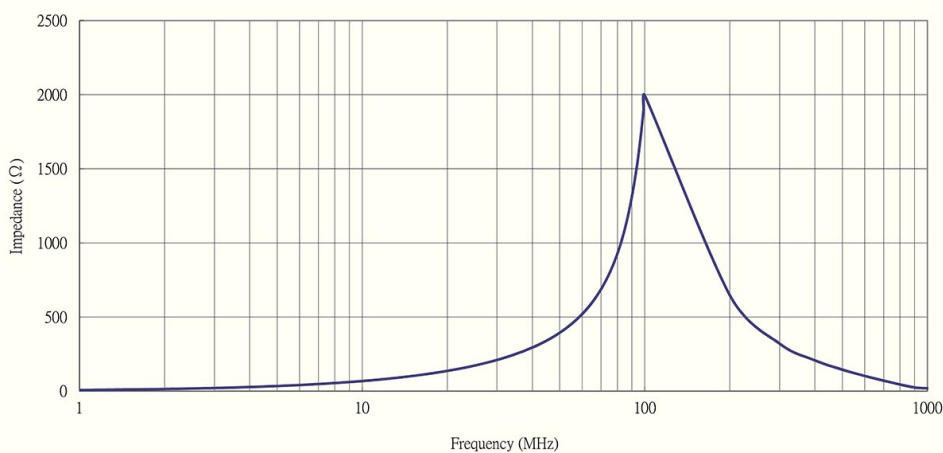

Outline Dimensions

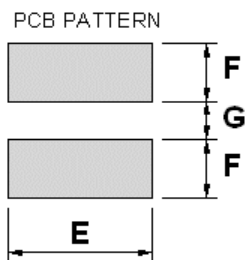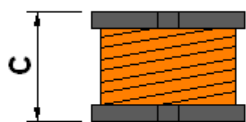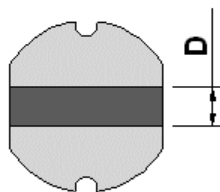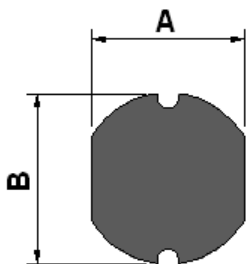

Dimensions [mm]

A	5.2 ± 0.5
B	5.8 ± 0.5
C	4.5 ± 0.55
D	2.3 typ.
E	5.5
F	2.15
G	1.7

All specifications valid at +25°C, unless otherwise stated.